

NB100-62922

Spastin Antibody

Unit Size

0.5 ml

Concentration

5 mg/ml

Storage

Store at 4C short term. Aliquot and store at -20C long term. Avoid freeze-thaw cycles.

Applications

WB, ELISA

Species

Human

Host

Rabbit

Clonality

Polyclonal

Purity

Affinity purified

Preservative

0.09% Sodium Azide

Specificity/Sensitivity

This product recognises an epitope between amino acids 130-142 of human spastin. The antibody has been tested for cross reactivity against the following peptides. Spastin 171-185 peptide <=0.1% Spastin 204-215 peptide <=0.1% Spastin 561-573 peptide <=0.1% Determined by competitive ELISA

Immunogen

Synthetic peptide corresponding to the amino acids 130 - 142 human spastin conjugated to Keyhole limpet Haemocyanin.

Recommended Dilutions

ELISA, Western Blot 1/100-1/1000

Buffer


Phosphate buffered saline

Uses

This antibody is useful for ELISA

Images

Western Blot: Spastin Antibody [NB100-62922] - Human brain lysate probed with RABBIT ANTI HUMAN SPASTIN

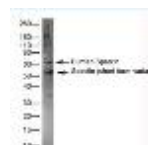

Updated 3/9/2013 2.0

Limitations: This product is for research use only and is not approved for use in humans or in clinical diagnosis. Products are guaranteed for six months from the date of receipt except for peptides and proteins which are guaranteed for 3 months. **For more information on our guarantee, please visit www.novusbio.com/guarantee.**

Novus USA

8100 Southpark Way, A-8
 Littleton, CO 80120
 p) 888-506-6887
 p) 303-730-1950
 f) 303-730-1966
novus@novusbio.com

Novus Canada

461 North Service Road West,
 Unit B37
 Oakville, ON L6M 2V5
 p) 855-668-8722
 f) 905-827-6402
canada@novusbio.com

Novus Europe

12 Cambridge Science Park
 Cambridge, UK CB4 0FQ
 UK: p) +44-1223-426-001, f) +44-871-971-1635
 DE: p) +49-6922-22340-60, f) +49-0800-58926-79
 IT: p) +39-02-4032-6786, f) +39-02-4032-6340
 FR: p) +33-1-76-77-45-30, f) +33-1-76-77-45-31
europe@novusbio.com

