

NB100-60644

Thymidine Kinase 1 Antibody

Unit Size

0.1 mg

Concentration

1.0 mg/ml

Storage

Store at 4°C. Do not freeze.

Applications

WB, IP

Species

Human

Host

Rabbit

Clonality

Polyclonal

Purity

Immunogen affinity purified

Preservative

0.09% Sodium Azide

Immunogen

The immunogen recognized by this antibody maps to a region between residue 205 and 234 of human thymidine kinase 1 using the numbering given in entry NP_003249.1 (GeneID 7083).

Recommended Dilutions

Immunoprecipitation 2-5 ug/mg lysate, Western Blot 1:2000-1:10000

Buffer


Tris-citrate/phosphate buffer, pH 7 to 8

Uses

Western Blot and Immunoprecipitation

Images

Western Blot: Thymidine Kinase 1 Antibody [NB100-60644] - Detection of Human TK1 on HeLa whole cell lysate using NB100-60644. TK1 was also immunoprecipitated by rabbit anti-TK1 antibody NB100-60643.

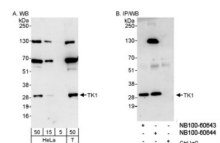

Updated 3/9/2013 2.0

Limitations: This product is for research use only and is not approved for use in humans or in clinical diagnosis. Products are guaranteed for six months from the date of receipt except for peptides and proteins which are guaranteed for 3 months. **For more information on our guarantee, please visit www.novusbio.com/guarantee.**

Novus USA

8100 Southpark Way, A-8
 Littleton, CO 80120
 p) 888-506-6887
 p) 303-730-1950
 f) 303-730-1966
novus@novusbio.com

Novus Canada

461 North Service Road West,
 Unit B37
 Oakville, ON L6M 2V5
 p) 855-668-8722
 f) 905-827-6402
canada@novusbio.com

Novus Europe

12 Cambridge Science Park
 Cambridge, UK CB4 0FQ
 UK: p) +44-1223-426-001, f) +44-871-971-1635
 DE: p) +49-6922-22340-60, f) +49-0800-58926-79
 IT: p) +39-02-4032-6786, f) +39-02-4032-6340
 FR: p) +33-1-76-77-45-30, f) +33-1-76-77-45-31
europe@novusbio.com

