

NB100-61622**UACA Antibody****Unit Size**

0.1 mg

Concentration

1.0 mg/ml

Storage

Store at 4C. Do not freeze.

Applications

WB, IHC, IHC-P, IP

Species

Human

Host

Rabbit

Clonality

Polyclonal

Purity

Immunogen affinity purified

Preservative

0.09% Sodium Azide

Immunogen

The immunogen recognized by this antibody maps to a region between residue 675 and 725 of human uveal autoantigen with coiled-coil domains and ankyrin repeats using the numbering given in entry NP_060473.2 (GeneID 55075).

Recommended Dilutions

Immunohistochemistry, Immunohistochemistry-Paraffin 1:100 - 1:500, Immunoprecipitation 2-5 ug/mg lysate, Western Blot

Buffer

Tris-citrate/phosphate buffer, pH 7 to 8


Uses

This antibody is useful for Immunoprecipitation. Western Blot: Not recommended.

Images (more available at www.novusbio.com/NB100-61622)

Western Blot: UACA Antibody [NB100-61622] - Detection of Human UACA by Western Blot of Immunoprecipitates. Samples: Whole cell lysate (1 mg for IP, 20% of IP loaded) from HeLa cells. Antibodies: Affinity purified rabbit anti-UACA antibody... See more at www.novusbio.com/NB100-61622

Immunohistochemistry-Paraffin: UACA Antibody [NB100-61622] - FFPE section of human breast carcinoma. Affinity purified rabbit anti-UACA used at a dilution of 1:250.

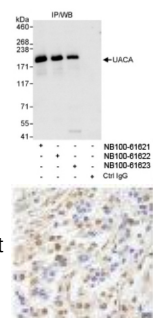

Updated 3/9/2013 2.0

Limitations: This product is for research use only and is not approved for use in humans or in clinical diagnosis. Products are guaranteed for six months from the date of receipt except for peptides and proteins which are guaranteed for 3 months. **For more information on our guarantee, please visit www.novusbio.com/guarantee.**

Novus USA

8100 Southpark Way, A-8
 Littleton, CO 80120
 p) 888-506-6887
 p) 303-730-1950
 f) 303-730-1966
novus@novusbio.com

Novus Canada

461 North Service Road West,
 Unit B37
 Oakville, ON L6M 2V5
 p) 855-668-8722
 f) 905-827-6402
canada@novusbio.com

Novus Europe

12 Cambridge Science Park
 Cambridge, UK CB4 0FQ
 UK: p) +44-1223-426-001, f) +44-871-971-1635
 DE: p) +49-6922-22340-60, f) +49-0800-58926-79
 IT: p) +39-02-4032-6786, f) +39-02-4032-6340
 FR: p) +33-1-76-77-45-30, f) +33-1-76-77-45-31
europe@novusbio.com

