

NB100-1910**MIF Antibody****Unit Size**

0.05 mg

Concentration

0.2 mg/ml

Storage

Aliquot and store at -20C or -80C. Avoid freeze-thaw cycles.

Applications

WB, IP

Species

Mouse, Rat

Molecular Weight

12kDa

Host

Rabbit

Clonality

Polyclonal

Isotype

IgG

Purity

Affinity purified

Preservative

0.01% Thimerosal

Specificity/Sensitivity

MIF

Immunogen

Synthetic peptide surrounding amino acid 67 of human MIF (CAG46452).

Recommended Dilutions

Immunoprecipitation 5-10 ug/ml

 
Western Blot 0.5-4 ug/ml

Buffer


PBS, pH 7.2, containing 30% glycerol and 0.5% BSA

Images

Western Blot: MIF Antibody [NB100-1910] - Western blot analysis of MIF expression in LPS stimulated RAW cell lysate.



Western Blot: MIF Antibody [NB100-1910] - Western blot analysis of MIF expression in lysates from Jurkat (Lane 1, 2), 3T3 (Lane 3) and rat kidney (Lane 4).

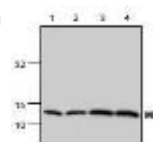

Updated 3/9/2013 2.0

Limitations: This product is for research use only and is not approved for use in humans or in clinical diagnosis. Products are guaranteed for six months from the date of receipt except for peptides and proteins which are guaranteed for 3 months. **For more information on our guarantee, please visit www.novusbio.com/guarantee.**

Novus USA

8100 Southpark Way, A-8
 Littleton, CO 80120
 p) 888-506-6887
 p) 303-730-1950
 f) 303-730-1966
novus@novusbio.com

Novus Canada

461 North Service Road West,
 Unit B37
 Oakville, ON L6M 2V5
 p) 855-668-8722
 f) 905-827-6402
canada@novusbio.com

Novus Europe

12 Cambridge Science Park
 Cambridge, UK CB4 0FQ
 UK: p) +44-1223-426-001, f) +44-871-971-1635
 DE: p) +49-6922-22340-60, f) +49-0800-58926-79
 IT: p) +39-02-4032-6786, f) +39-02-4032-6340
 FR: p) +33-1-76-77-45-30, f) +33-1-76-77-45-31
europe@novusbio.com

