

NB100-2311**TYRO3 Antibody****Unit Size**

0.1 mg

Concentration

1.0 mg/ml

Storage

Store at 4°C. Do not freeze.

Applications

WB, IP

Species

Human

Molecular Weight

97kDa

Host

Rabbit

Clonality

Polyclonal

Purity

Immunogen affinity purified

Preservative

0.09% Sodium Azide

Specificity/Sensitivity

TYRO3

Immunogen

The immunogen recognized by this antibody maps to a region between residues 850 and the C-terminus (residue 890) of human Tyro3 Tyrosine Kinase using the numbering given in Swiss-Prot entry Q06418 (GeneID 7301).

Recommended Dilutions

Immunoprecipitation 5 -20 ug/mg lysate, Western Blot 1:5000 - 1:20000

Buffer


Tris-citrate/phosphate buffer, pH 7 to 8

Uses

This antibody is useful for Prepare working dilution immediately before use.

Images

Western Blot: TYRO3 Antibody [NB100-2311] - Detection of Human Tyro3 on HeLa whole cell lysate using NB100-2311. Another rabbit polyclonal antibody was used in IP as a negative control (Ctrl IP).

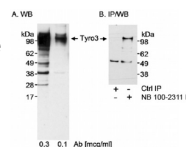

Updated 3/9/2013 2.0

Limitations: This product is for research use only and is not approved for use in humans or in clinical diagnosis. Products are guaranteed for six months from the date of receipt except for peptides and proteins which are guaranteed for 3 months. **For more information on our guarantee, please visit www.novusbio.com/guarantee.**

Novus USA

8100 Southpark Way, A-8
 Littleton, CO 80120
 p) 888-506-6887
 p) 303-730-1950
 f) 303-730-1966
novus@novusbio.com

Novus Canada

461 North Service Road West,
 Unit B37
 Oakville, ON L6M 2V5
 p) 855-668-8722
 f) 905-827-6402
canada@novusbio.com

Novus Europe

12 Cambridge Science Park
 Cambridge, UK CB4 0FQ
 UK: p) +44-1223-426-001, f) +44-871-971-1635
 DE: p) +49-6922-22340-60, f) +49-0800-58926-79
 IT: p) +39-02-4032-6786, f) +39-02-4032-6340
 FR: p) +33-1-76-77-45-30, f) +33-1-76-77-45-31
europe@novusbio.com

