

NB100-686**VEGF Receptor 2 Antibody****Unit Size**

0.5 ml

Concentration

0.1 mg/ml

Storage

Store at 4C. Do not freeze.

Applications

IHC, IHC-Fr, IHC-P

Species

Human, Mouse, Rat

Host

Rabbit

Clonality

Polyclonal

Purity

Affinity purified

Preservative

Sodium Azide

Marker

Hemangioblast Marker, Stem Cell Marker

Immunogen

A synthetic peptide derived from the C-terminus of the precursor form of the human VEGF Receptor 2.

Recommended Dilutions

Immunohistochemistry-Paraffin 1:50-1:100, Immunohistochemistry-Frozen 1:50-1:100, Immunohistochemistry

Buffer

PBS

Uses


For IHC-P: Sections require high temperature antigen unmasking with 10 mM citrate buffer, pH 6.0 prior to immunostaining.

References

Ostalska-Nowicka D, Malinska A, Zabel M, Witkiewicz W, Nowicki M. Nephrotic syndrome unfavorable course correlates with downregulation of podocyte vascular endothelial growth factor receptor (VEGFR)-2. Folia Histochem Cytobiol;49(3):472-8. 2011. [PMID: 22038228] (Human)

Images

Immunohistochemistry-Paraffin: VEGF Receptor 2 Antibody - Hemangioblast Marker/Stem Cell Marker [NB100-686] - Formalin fixed paraffin embedded human angiosarcoma stained with Flk-1 antibody.

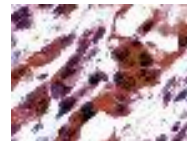

Updated 3/9/2013 2.0

Limitations: This product is for research use only and is not approved for use in humans or in clinical diagnosis. Products are guaranteed for six months from the date of receipt except for peptides and proteins which are guaranteed for 3 months. **For more information on our guarantee, please visit www.novusbio.com/guarantee.**

Novus USA
 8100 Southpark Way, A-8
 Littleton, CO 80120
 p) 888-506-6887
 p) 303-730-1950
 f) 303-730-1966
novus@novusbio.com
Novus Canada
 461 North Service Road West,
 Unit B37
 Oakville, ON L6M 2V5
 p) 855-668-8722
 f) 905-827-6402
canada@novusbio.com
Novus Europe
 12 Cambridge Science Park
 Cambridge, UK CB4 0FQ
 UK: p) +44-1223-426-001, f) +44-871-971-1635
 DE: p) +49-6922-22340-60, f) +49-0800-58926-79
 IT: p) +39-02-4032-6786, f) +39-02-4032-6340
 FR: p) +33-1-76-77-45-30, f) +33-1-76-77-45-31
europe@novusbio.com
