




DHX9 Antibody [3G7]

CATALOG NUMBER: 51-690

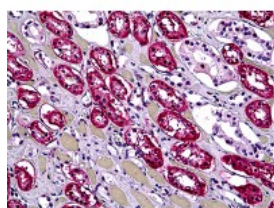

Immunohistochemistry of human kidney tubules stained using DHX9 Monoclonal Antibody.

Specifications

SPECIES REACTIVITY:	Human
TESTED APPLICATIONS:	ELISA, IF, IHC, WB
APPLICATIONS:	DHX9 antibody can be used in Western Blot, and immunohistochemistry starting at 10 ug/mL.
USER NOTE:	Optimal dilutions for each application to be determined by the researcher.
IMMUNOGEN:	Recombinant protein
HOST SPECIES:	Mouse

Properties

PURIFICATION:	Protein A Column
PHYSICAL STATE:	Liquid
BUFFER:	PBS, pH 7.2
STORAGE CONDITIONS:	DHX9 antibody can be stored short term 4 °C. For long term storage aliquot and store at -20 °C. As with all antibodies avoid freeze/thaw cycles.
CLONALITY:	Monoclonal
ISOTYPE:	IgG1,k
CONJUGATE:	Unconjugated

Additional Info

ALTERNATE NAMES:	DHX9, ATP-dependent RNA helicase A, DDX9, DEAH box protein 9, NDH II, NDHII, LKP, NDH2, Nuclear DNA helicase II, RHA, Leukophysin
ACCESSION NO.:	Q08211
PROTEIN GI NO.:	116241330
OFFICIAL SYMBOL:	DHX9
GENE ID:	1660

Background

