




Prohibitin Antibody [3F4-2B2]

CATALOG NUMBER: 51-711

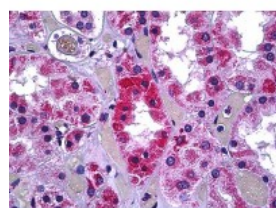

Immunohistochemistry of human kidney
tubules stained using Prohibitin Monoclonal
Antibody.

Specifications

SPECIES REACTIVITY:	Human
TESTED APPLICATIONS:	ELISA, IF, IHC, WB
APPLICATIONS:	Prohibitin antibody can be used in Western Blot starting at 0.5 - 1 ug/mL, and immunohistochemistry starting at 10 ug/mL.
USER NOTE:	Optimal dilutions for each application to be determined by the researcher.
IMMUNOGEN:	Recombinant protein
HOST SPECIES:	Mouse

Properties

PURIFICATION:	Protein A Column
PHYSICAL STATE:	Liquid
BUFFER:	PBS, pH 7.2
STORAGE CONDITIONS:	Prohibitin antibody can be stored short term 4 °C. For long term storage aliquot and store at -20 °C. As with all antibodies avoid freeze/thaw cycles.
CLONALITY:	Monoclonal
ISOTYPE:	IgG2a,k
CONJUGATE:	Unconjugated

Additional Info

ALTERNATE NAMES:	PHB, PHB1, Prohibitin
ACCESSION NO.:	P35232
PROTEIN GI NO.:	464371
OFFICIAL SYMBOL:	PHB
GENE ID:	5245

Background

