




SGK1 Antibody [3E3]

CATALOG NUMBER: 51-801

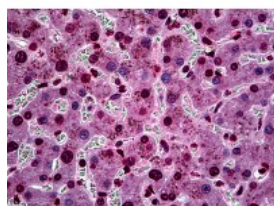

Immunohistochemistry of human liver tissue stained using SGK1 Monoclonal Antibody.

Specifications

SPECIES REACTIVITY:	Human
TESTED APPLICATIONS:	ELISA, IF, IHC, WB
APPLICATIONS:	SGK1 antibody can be used in Western Blot starting at 2 ug/mL, immunohistochemistry starting at 5 ug/mL, immunocytochemistry, and immunoprecipitation
USER NOTE:	Optimal dilutions for each application to be determined by the researcher.
IMMUNOGEN:	Recombinant protein
HOST SPECIES:	Mouse

Properties

PURIFICATION:	Protein A Column
PHYSICAL STATE:	Liquid
BUFFER:	PBS, pH 7.2
STORAGE CONDITIONS:	SGK1 antibody can be stored short term 4 °C. For long term storage aliquot and store at -20 °C. As with all antibodies avoid freeze/thaw cycles.
CLONALITY:	Monoclonal
ISOTYPE:	IgG2b,k
CONJUGATE:	Unconjugated

Additional Info

ALTERNATE NAMES:	SGK1, Hsgk, Hsgk1, SGK, Sgk1 variant i3
ACCESSION NO.:	O00141
PROTEIN GI NO.:	90185131
OFFICIAL SYMBOL:	SGK1
GENE ID:	6446

Background

