




ARNT Antibody [3D10]

CATALOG NUMBER: 51-884

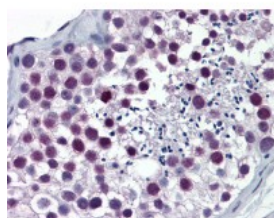

Immunohistochemistry of human testis tissue stained using ARNT Monoclonal Antibody.

Specifications

SPECIES REACTIVITY:	Human
TESTED APPLICATIONS:	ELISA, IF, IHC, WB
APPLICATIONS:	ARNT antibody can be used in Western Blot starting at 0.5 ug/mL, and immunohistochemistry starting at 10 ug/mL.
USER NOTE:	Optimal dilutions for each application to be determined by the researcher.
IMMUNOGEN:	ARNT (AAH60838, 1 a.a. ~ 110 a.a) partial recombinant protein with GST tag. MW of the GST tag alone is 26 KDa.
HOST SPECIES:	Mouse

Properties

PURIFICATION:	Protein A Column
PHYSICAL STATE:	Liquid
BUFFER:	PBS, pH 7.2
STORAGE CONDITIONS:	Aliquot and store ARNT antibody at -20 °C or -80 °C. As with all antibodies avoid freeze/thaw cycles.
CLONALITY:	Monoclonal
ISOTYPE:	IgG2a,k
CONJUGATE:	Unconjugated

Additional Info

ALTERNATE NAMES:	ARNT, ARNT protein, BHLHe2, HIF-1beta, HIF1-beta, HIF1BETA, TANGO, HIF-1-beta, HIF1B
ACCESSION NO.:	P27540
PROTEIN GI NO.:	114163
OFFICIAL SYMBOL:	ARNT
GENE ID:	405

Background

