




RBM3 Antibody [4D6]

CATALOG NUMBER: 51-917

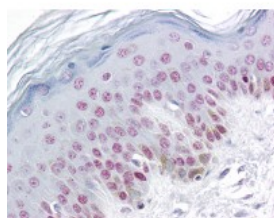

Immunohistochemistry of human skin tissue stained using RBM3 Monoclonal Antibody.

Specifications

SPECIES REACTIVITY:	Human
TESTED APPLICATIONS:	ELISA, IHC, WB
APPLICATIONS:	RBM3 antibody can be used in Western Blot starting at 1 - 3 ug/mL, and immunohistochemistry starting at 10 ug/mL.
USER NOTE:	Optimal dilutions for each application to be determined by the researcher.
IMMUNOGEN:	RBM3 (NP_006734, 1 a.a. ~ 81 a.a) partial recombinant protein with GST tag. MW of the GST tag alone is 26 KDa.
HOST SPECIES:	Mouse

Properties

PURIFICATION:	Protein A Column
PHYSICAL STATE:	Liquid
BUFFER:	PBS, pH 7.2
STORAGE CONDITIONS:	Aliquot and store RBM3 antibody at -20 °C or -80 °C. As with all antibodies avoid freeze/thaw cycles.
CLONALITY:	Monoclonal
ISOTYPE:	IgG1,k
CONJUGATE:	Unconjugated

Additional Info

ALTERNATE NAMES:	RBM3, IS1-RNPL, RNA binding motif protein 3, RNPL, RNA-binding motif protein 3, Putative RNA-binding protein 3
ACCESSION NO.:	P98179
PROTEIN GI NO.:	1710620
OFFICIAL SYMBOL:	RBM3
GENE ID:	5935

FOR RESEARCH USE ONLY

December 13, 2016