




Importin 5 Antibody [1C4]

CATALOG NUMBER: 51-969

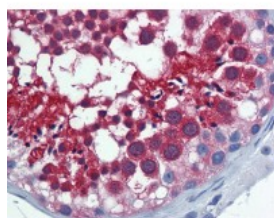

Immunohistochemistry of human testis tissue stained using Importin 5 Monoclonal Antibody.

Specifications

SPECIES REACTIVITY:	Human
TESTED APPLICATIONS:	ELISA, IHC, WB
APPLICATIONS:	Importin 5 antibody can be used in Western Blot starting at 2 ug/mL, immunohistochemistry starting at 10 ug/mL, and immunoprecipitation.
USER NOTE:	Optimal dilutions for each application to be determined by the researcher.
IMMUNOGEN:	RANBP5 (AAH01497, 1 a.a. ~ 101 a.a) partial recombinant protein with GST tag. MW of the GST tag alone is 26 KDa.
HOST SPECIES:	Mouse

Properties

PURIFICATION:	Protein A Column
PHYSICAL STATE:	Liquid
BUFFER:	PBS, pH 7.2
STORAGE CONDITIONS:	Aliquot and store Importin 5 antibody at -20 °C or -80 °C. As with all antibodies avoid freeze/thaw cycles.
CLONALITY:	Monoclonal
ISOTYPE:	IgG1,k
CONJUGATE:	Unconjugated

Additional Info

ALTERNATE NAMES:	IPO5, IMB3, Importin 5, Importin subunit beta-3, Imp5, Importin-5, Importin beta-3 subunit, Karyopherin beta-3, KPNB3, Karyopherin (importin) beta 3, Pse1, RAN binding protein 5, Ran-binding protein 5, Ran_GTP binding protein 5, RANBP5
ACCESSION NO.:	O00410
PROTEIN GI NO.:	4033763
OFFICIAL SYMBOL:	IPO5
GENE ID:	3843

