




MAPK3 Antibody [3C9]

CATALOG NUMBER: 51-981

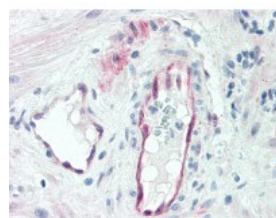

Immunohistochemistry of human vessels
tissue stained using MAPK3 Monoclonal
Antibody.

Specifications

SPECIES REACTIVITY:	Human
TESTED APPLICATIONS:	ELISA, IF, IHC, WB
APPLICATIONS:	MAPK3 antibody can be used in Western Blot starting at 1 - 3 ug/mL, and immunohistochemistry starting at 10 ug/mL.
USER NOTE:	Optimal dilutions for each application to be determined by the researcher.
IMMUNOGEN:	MAPK3 (AAH13992, 279 a.a. ~ 379 a.a) partial recombinant protein with GST tag. MW of the GST tag alone is 26 KDa.
HOST SPECIES:	Mouse

Properties

PURIFICATION:	Protein A Column
PHYSICAL STATE:	Liquid
BUFFER:	PBS, pH 7.2
STORAGE CONDITIONS:	Store MAPK3 antibody at -20 °C or lower. As with all antibodies avoid freeze/thaw cycles.
CLONALITY:	Monoclonal
ISOTYPE:	IgG2a,k
CONJUGATE:	Unconjugated

Additional Info

ALTERNATE NAMES:	MAPK3, ERK-1, ERT2, HUMKER1A, HS44KDAP, MAP kinase 1, MAP kinase isoform p44, MAPK 1, MAPK 3, p44, p44MAPK, p44-MAPK, p44ERK1, Insulin-stimulated MAP2 kinase, MAP kinase 3, p44-ERK1, ERK1, PRKM3
ACCESSION NO.:	P27361
PROTEIN GI NO.:	232066
OFFICIAL SYMBOL:	MAPK3
GENE ID:	5595

