




ABHD5 Antibody [1F3]

CATALOG NUMBER: 70-014

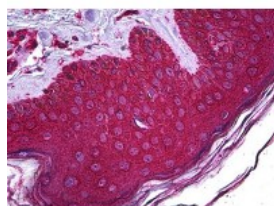

Immunohistochemistry of human skin tissue stained using ABHD5 Monoclonal Antibody.

Specifications

SPECIES REACTIVITY:	Human
TESTED APPLICATIONS:	ELISA, IHC, WB
APPLICATIONS:	ABHD5 antibody can be used in Western Blot starting at 2 ug/mL, and immunohistochemistry starting at 10 ug/mL.
USER NOTE:	Optimal dilutions for each application to be determined by the researcher.
IMMUNOGEN:	ABHD5 (AAH21958, 1 a.a. ~ 350 a.a) full length recombinant protein with GST tag. MW of the GST tag alone is 26 KDa.
HOST SPECIES:	Mouse

Properties

PURIFICATION:	Protein A Column
PHYSICAL STATE:	Liquid
BUFFER:	PBS, pH 7.2
STORAGE CONDITIONS:	ABHD5 antibody can be stored short term 4 °C. For long term storage aliquot and store at -20 °C. As with all antibodies avoid freeze/thaw cycles.
CLONALITY:	Monoclonal
ISOTYPE:	IgG2a,k
CONJUGATE:	Unconjugated

Additional Info

ALTERNATE NAMES:	ABHD5, CDS, CGI-58, IECN2, NCIE2, CGI58
ACCESSION NO.:	Q8WTS1
PROTEIN GI NO.:	73921640
OFFICIAL SYMBOL:	ABHD5
GENE ID:	51099

