




Histone Deacetylase 4 Antibody

CATALOG NUMBER: 49-245

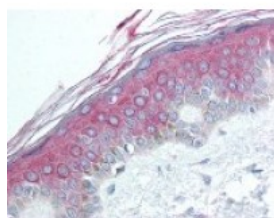

Immunohistochemistry staining of Histone Deacetylase 4 in skin tissue using Histone Deacetylase 4 Antibody.

Specifications

SPECIES REACTIVITY:	Human, Mouse
TESTED APPLICATIONS:	IF, IHC, WB
APPLICATIONS:	Histone Deacetylase 4 antibody can be used in ELISA, Western Blot, immunohistochemistry starting at 20 ug/mL, immunoprecipitation, and flow cytometry.
USER NOTE:	Optimal dilutions for each application to be determined by the researcher.
IMMUNOGEN:	Histone Deacetylase 4 antibody was raised against recombinant (partial), N-Terminal region of Histone Deacetylase 4 (Mouse).
HOST SPECIES:	Rabbit

Properties

PURIFICATION:	Immunoaffinity Chromatography
PHYSICAL STATE:	Liquid
BUFFER:	Phosphate-buffered solution, pH 7.2, 0.09% sodium azide, 50% glycerol.
STORAGE CONDITIONS:	Aliquot and store Histone Deacetylase 4 antibody at -20 °C. As with all antibodies avoid freeze/thaw cycles.
CLONALITY:	Polyclonal
ISOTYPE:	IgG
CONJUGATE:	Unconjugated

Additional Info

ALTERNATE NAMES:	HDAC4, BDMR, AHO3, Histone deacetylase A, HD4, HA6116, HDAC-A, HDACA, Histone deacetylase 4, HDAC-4, KIAA0288
ACCESSION NO.:	P56524
PROTEIN GI NO.:	259016348
OFFICIAL SYMBOL:	HDAC4
GENE ID:	9759

FOR RESEARCH USE ONLY

December 13, 2016