




LRRC7 Antibody

CATALOG NUMBER: 51-134

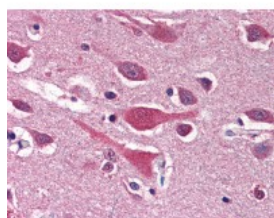

Immunohistochemistry staining of LRRC7
in brain cortex tissue using LRRC7
Antibody.

Specifications

SPECIES REACTIVITY:	Human, Mouse, Rat
TESTED APPLICATIONS:	ELISA, IHC, WB
APPLICATIONS:	LRRC7 antibody can be used in Western Blot, immunohistochemistry starting at 20 ug/mL, immunofluorescence, and immunoprecipitation
USER NOTE:	Optimal dilutions for each application to be determined by the researcher.
IMMUNOGEN:	LRRC7 antibody was raised against a synthetic peptide of LRRC7 (Human).
HOST SPECIES:	Rabbit

Properties

PURIFICATION:	Immunoaffinity Chromatography
PHYSICAL STATE:	Liquid
BUFFER:	PBS, 0.01% sodium azide, 50% glycerol.
STORAGE CONDITIONS:	Store LRRC7 antibody at 4 °C or -20 °C. As with all antibodies avoid freeze/thaw cycles.
CLONALITY:	Polyclonal
CONJUGATE:	Unconjugated

Additional Info

ALTERNATE NAMES:	LRRC7, DENSIN, Densin-180, KIAA1365, Protein LAP1, LAP1
ACCESSION NO.:	Q96NW7
PROTEIN GI NO.:	50401129
OFFICIAL SYMBOL:	LRRC7
GENE ID:	57554

Background

FOR RESEARCH USE ONLY

