




PCNA Antibody

CATALOG NUMBER: 51-135

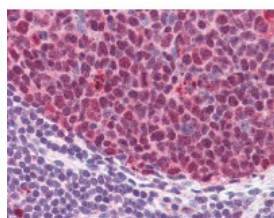

Immunohistochemistry staining of PCNA
in colon tissue using PCNA Antibody.

Specifications

SPECIES REACTIVITY:	Human, Mouse, Rat
TESTED APPLICATIONS:	IHC, IP, WB
APPLICATIONS:	PCNA antibody can be used in ELISA, Western Blot, immunohistochemistry starting at 10 ug/mL, and immunofluorescence starting at 10 ug/mL.
USER NOTE:	Optimal dilutions for each application to be determined by the researcher.
IMMUNOGEN:	PCNA antibody was raised against a synthetic peptide corresponding to the C-Terminus of human PCNA (Human).
HOST SPECIES:	Rabbit

Properties

PURIFICATION:	Immunoaffinity Chromatography
PHYSICAL STATE:	Liquid
BUFFER:	PBS, pH 7.2, 50% glycerol, 1% BSA, 0.02% Thimerosal.
STORAGE CONDITIONS:	Store PCNA antibody at 4 °C or -20 °C. As with all antibodies avoid freeze/thaw cycles.
CLONALITY:	Polyclonal
CONJUGATE:	Unconjugated

Additional Info

ALTERNATE NAMES:	PCNA, Cyclin
ACCESSION NO.:	P12004
PROTEIN GI NO.:	129694
OFFICIAL SYMBOL:	PCNA
GENE ID:	5111

Background

FOR RESEARCH USE ONLY

