




Calponin Antibody [2F5-1H4]

CATALOG NUMBER: 51-442

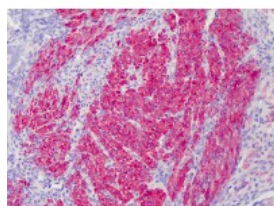

Immunohistochemistry of human myometrium tissue stained using Calponin Monoclonal Antibody.

Specifications

SPECIES REACTIVITY:	Human
TESTED APPLICATIONS:	ELISA, IHC, WB
APPLICATIONS:	Calponin antibody can be used in Western Blot starting at 2.5 - 5 ug/mL, and immunohistochemistry starting at 5 ug/mL.
USER NOTE:	Optimal dilutions for each application to be determined by the researcher.
IMMUNOGEN:	Human CNN1
HOST SPECIES:	Mouse

Properties

PURIFICATION:	Protein A Column
PHYSICAL STATE:	Liquid
BUFFER:	PBS, pH 7.2
STORAGE CONDITIONS:	Store Calponin antibody at -20 °C. Aliquot to avoid freeze/thaw cycles.
CLONALITY:	Monoclonal
ISOTYPE:	IgG1,k
CONJUGATE:	Unconjugated

Additional Info

ALTERNATE NAMES:	CNN1, Basic calponin, Calponin, Calponin-1, Calponins, basic, Calponin H1, smooth muscle, SMCC, Sm-Calp
ACCESSION NO.:	P51911
PROTEIN GI NO.:	2829431
OFFICIAL SYMBOL:	CNN1
GENE ID:	1264

Background

