




HOXB7 Antibody [4C6]

CATALOG NUMBER: 51-471

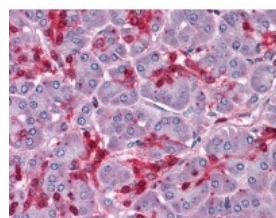

Immunohistochemistry of human pancreas
tissue stained using HOXB7 Monoclonal
Antibody.

Specifications

SPECIES REACTIVITY:	Human
TESTED APPLICATIONS:	ELISA, IHC, WB
APPLICATIONS:	HOXB7 antibody can be used in Western Blot starting at 1 - 2 ug/mL, and immunohistochemistry starting at 2.5 ug/mL.
USER NOTE:	Optimal dilutions for each application to be determined by the researcher.
IMMUNOGEN:	HOXB7 (NP_004493, 55 a.a. ~ 121 a.a) partial recombinant protein with GST tag. MW of the GST tag alone is 26 KDa.
HOST SPECIES:	Mouse

Properties

PURIFICATION:	Protein A Column
PHYSICAL STATE:	Liquid
BUFFER:	PBS, pH 7.2
STORAGE CONDITIONS:	Store HOXB7 antibody at -20 °C. Aliquot to avoid freeze/thaw cycles.
CLONALITY:	Monoclonal
ISOTYPE:	IgG1,k
CONJUGATE:	Unconjugated

Additional Info

ALTERNATE NAMES:	HOXB7, Homeo box c1 protein, Homeobox protein HHO.C1, Hox-2.3, Homeo box 2C, Homeobox B7, Homeobox protein Hox-B7, HHO.C1, Homeo box B7, Homeobox protein Hox-2C, HOX2, HOX2C
ACCESSION NO.:	P09629
PROTEIN GI NO.:	311033482
OFFICIAL SYMBOL:	HOXB7
GENE ID:	3217

FOR RESEARCH USE ONLY

December 13, 2016