




MYH9 Antibody [4H3]

CATALOG NUMBER: 51-769

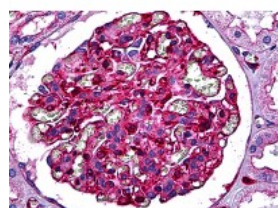

Immunohistochemistry of human kidney,
Glomeruli stained using MYH9 Monoclonal
Antibody.

Specifications

| | |
|-----------------------------|--------------------------------------------------------------------------------------------------------------------------------|
| SPECIES REACTIVITY: | Human |
| TESTED APPLICATIONS: | ELISA, IF, IHC, WB |
| APPLICATIONS: | MYH9 antibody can be used in Western Blot, immunohistochemistry starting at 20 ug/mL, immunoprecipitation, and flow cytometry. |
| USER NOTE: | Optimal dilutions for each application to be determined by the researcher. |
| IMMUNOGEN: | Recombinant protein |
| HOST SPECIES: | Mouse |

Properties

| | |
|----------------------------|--------------------------------------------------------------------------------------------------------------------------------------------------|
| PURIFICATION: | Protein A Column |
| PHYSICAL STATE: | Liquid |
| BUFFER: | PBS, pH 7.2 |
| STORAGE CONDITIONS: | MYH9 antibody can be stored short term 4 °C. For long term storage aliquot and store at -20 °C. As with all antibodies avoid freeze/thaw cycles. |
| CLONALITY: | Monoclonal |
| ISOTYPE: | IgG2b,k |
| CONJUGATE: | Unconjugated |

Additional Info

| | |
|-------------------------|---------------------------------------------------------------------------------------------------------------------------|
| ALTERNATE NAMES: | MYH9, BDPLT6, FTNS, MHA, Myosin heavy chain 9, NMMHC-IIA, NMMHC-A, Myosin-9, NMMHC II-a, DFNA17, EPSTS, NMHC-II-A, NMMHCA |
| ACCESSION NO.: | P35579 |
| PROTEIN GI NO.: | 6166599 |
| OFFICIAL SYMBOL: | MYH9 |
| GENE ID: | 4627 |

FOR RESEARCH USE ONLY

December 13, 2016