




Olig1 Antibody

CATALOG NUMBER: 50-134

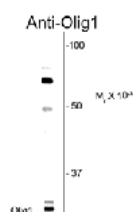

Western blot of neonatal rat brain lysate showing specific immunolabeling of the ~27k Olig1 protein.

Western blot of neonatal rat brain lysate showing specific immunolabeling of the ~27k Olig1 protein.

Specifications

SPECIES REACTIVITY:	Mouse, Rat
TESTED APPLICATIONS:	IHC, IP, WB
USER NOTE:	Optimal dilutions for each application to be determined by the researcher.
PREDICTED MOLECULAR WEIGHT:	27
IMMUNOGEN:	Recombinant mouse Olig1.
HOST SPECIES:	Rabbit

Properties

PURIFICATION:	Protein A purified
PHYSICAL STATE:	Liquid
BUFFER:	100 uL in 100 mM Glycine, 200 mM Tris, pH 8.0
CLONALITY:	Polyclonal
CONJUGATE:	Unconjugated

Additional Info

ALTERNATE NAMES:	Olig-1, Bhlhb6, Oligo1, bHLHe21, A1836478, AW494459, Oligodendrocyte-specific bHLH transcription factor 1
ACCESSION NO.:	Q9JKN5
PROTEIN GI NO.:	22653897
OFFICIAL SYMBOL:	Olig1
GENE ID:	50914

Background

FOR RESEARCH USE ONLY