




CTNS Antibody

CATALOG NUMBER: 49-300

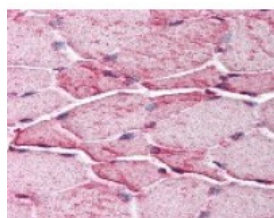

Immunohistochemistry staining of CTNS in skeletal muscle tissue using CTNS Antibody.

Specifications

SPECIES REACTIVITY:	Human
TESTED APPLICATIONS:	ELISA, IHC
APPLICATIONS:	CTNS antibody can be used in ELISA starting at 1:2000 - 1:10000, Western Blot starting at 1:500 - 1:1000, immunohistochemistry starting at 1:500, and immunoprecipitation
USER NOTE:	Optimal dilutions for each application to be determined by the researcher.
IMMUNOGEN:	CTNS antibody was raised against amino acids 268 - 285 of CTNS (Human).
HOST SPECIES:	Rabbit

Properties

PURIFICATION:	Protein G Column
PHYSICAL STATE:	Liquid
BUFFER:	PBS, 0.09% sodium azide.
STORAGE CONDITIONS:	Store CTNS antibody at 4 °C or -20 °C. As with all antibodies avoid freeze/thaw cycles.
CLONALITY:	Polyclonal
CONJUGATE:	Unconjugated

Additional Info

ALTERNATE NAMES:	CTNS, Cystinosis, Cystinosis, nephropathic, CTNS-LSB, PQLC4
ACCESSION NO.:	O60931
PROTEIN GI NO.:	269849555
OFFICIAL SYMBOL:	CTNS
GENE ID:	1497

Background

FOR RESEARCH USE ONLY

