




APOA4 Antibody [2D1C9]

CATALOG NUMBER: 51-307

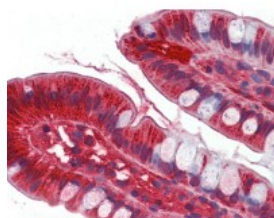

Immunohistochemistry of human small intestine tissue stained using APOA4 Monoclonal Antibody.

Specifications

SPECIES REACTIVITY:	Human
TESTED APPLICATIONS:	ELISA, IHC, WB
APPLICATIONS:	APOA4 antibody can be used in ELISA starting at 1:5000 - 1:25000, Western Blot starting at 1:2000 - 1:5000, immunohistochemistry starting at 10 - 20 ug/mL, and immunoprecipitation
USER NOTE:	Optimal dilutions for each application to be determined by the researcher.
IMMUNOGEN:	Purified recombinant fragment of APOA4 (aa21-396) expressed in E. Coli.
HOST SPECIES:	Mouse

Properties

PURIFICATION:	Ascites
PHYSICAL STATE:	Liquid
BUFFER:	0.03% sodium azide
STORAGE CONDITIONS:	APOA4 antibody should be stored long term (months) at -20 °C and short term (weeks) at 4 °C. As with all antibodies avoid freeze/thaw cycles.
CLONALITY:	Monoclonal
ISOTYPE:	IgG1
CONJUGATE:	Unconjugated

Additional Info

ALTERNATE NAMES:	APOA4, Apo-AIV, Apolipoprotein A-IV, Apolipoprotein A4, ApoA-IV
ACCESSION NO.:	P06727
PROTEIN GI NO.:	93163358
OFFICIAL SYMBOL:	APOA4
GENE ID:	337

Background

