




EGF Antibody [9D7F11]

CATALOG NUMBER: 51-387

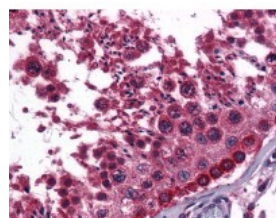

Immunohistochemistry of human testis
tissue stained using EGF Monoclonal
Antibody.

Specifications

SPECIES REACTIVITY:	Human
TESTED APPLICATIONS:	ELISA, IHC, WB
APPLICATIONS:	EGF antibody can be used in Western Blot starting at 2 ug/mL, and immunohistochemistry starting at 10 ug/mL.
USER NOTE:	Optimal dilutions for each application to be determined by the researcher.
IMMUNOGEN:	Recombinant protein
HOST SPECIES:	Mouse

Properties

PURIFICATION:	Ascites
PHYSICAL STATE:	Liquid
BUFFER:	0.03% sodium azide
STORAGE CONDITIONS:	EGF antibody should be stored long term (months) at -20 °C and short term (weeks) at 4 °C. As with all antibodies avoid freeze/thaw cycles.
CLONALITY:	Monoclonal
ISOTYPE:	IgG1
CONJUGATE:	Unconjugated

Additional Info

ALTERNATE NAMES:	EGF, Beta-urogastrone, HOMG4, URG, Epidermal growth factor, Pro-epidermal growth factor
ACCESSION NO.:	P01133
PROTEIN GI NO.:	251757262
OFFICIAL SYMBOL:	EGF
GENE ID:	1950

Background

