




AGXT Antibody [AT2T4]

CATALOG NUMBER: 51-413

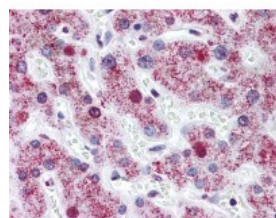

Immunohistochemistry of human liver tissue stained using AGXT Monoclonal Antibody.

Specifications

SPECIES REACTIVITY:	Human
TESTED APPLICATIONS:	IHC
APPLICATIONS:	AGXT antibody can be used in ELISA, Western Blot starting at 1:500 - 1:1000, and immunohistochemistry starting at 5 ug/mL.
USER NOTE:	Optimal dilutions for each application to be determined by the researcher.
HOST SPECIES:	Mouse

Properties

PURIFICATION:	Protein G Column
PHYSICAL STATE:	Liquid
BUFFER:	Phosphate buffered saline, pH 7.4, 0.1% sodium azide
STORAGE CONDITIONS:	Store AGXT antibody at 4 °C or -20 °C. As with all antibodies avoid freeze/thaw cycles.
CLONALITY:	Monoclonal
ISOTYPE:	IgG2b,k
CONJUGATE:	Unconjugated

Additional Info

ALTERNATE NAMES:	AGXT, AGXT1, AGT1, PH1, SPT, SPAT, TLH6
ACCESSION NO.:	P21549
PROTEIN GI NO.:	134855
OFFICIAL SYMBOL:	AGXT
GENE ID:	189

Background

FOR RESEARCH USE ONLY

