




APOA2 Antibody [1H6]

CATALOG NUMBER: 51-423

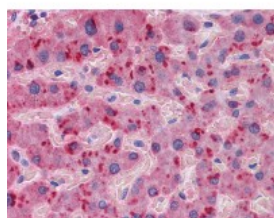

Immunohistochemistry of human liver tissue stained using APOA2 Monoclonal Antibody.

Specifications

SPECIES REACTIVITY:	Human
TESTED APPLICATIONS:	ELISA, IHC, WB
APPLICATIONS:	APOA2 antibody can be used in immunohistochemistry starting at 5 ug/mL.
USER NOTE:	Optimal dilutions for each application to be determined by the researcher.
IMMUNOGEN:	APOA2 (AAH05282, 1 a.a. ~ 101 a.a) full-length recombinant protein with GST tag. MW of the GST tag alone is 26 KDa.
HOST SPECIES:	Mouse

Properties

PURIFICATION:	Protein A Column
PHYSICAL STATE:	Liquid
BUFFER:	PBS, pH 7.2
STORAGE CONDITIONS:	Store APOA2 antibody at -20 °C. Aliquot to avoid freeze/thaw cycles.
CLONALITY:	Monoclonal
ISOTYPE:	IgG1,k
CONJUGATE:	Unconjugated

Additional Info

ALTERNATE NAMES:	APOA2, Apo-AII, ApoAII, ApoA-II, Apolipoprotein A-II, Apolipoprotein A2, Apolipoprotein A II
ACCESSION NO.:	P02652
PROTEIN GI NO.:	114000
OFFICIAL SYMBOL:	APOA2
GENE ID:	336

Background

