




## ART3 Antibody [3A2]

CATALOG NUMBER: 51-425

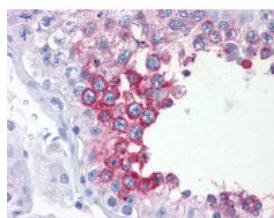

Immunohistochemistry of human testis tissue stained using ART3 Monoclonal Antibody.

### Specifications

<b>SPECIES REACTIVITY:</b>	Human
<b>TESTED APPLICATIONS:</b>	ELISA, IHC, WB
<b>APPLICATIONS:</b>	ART3 antibody can be used in Western Blot, and immunohistochemistry starting at 5 ug/mL.
<b>USER NOTE:</b>	Optimal dilutions for each application to be determined by the researcher.
<b>IMMUNOGEN:</b>	ART3 (NP_001170, 29 a.a. ~ 139 a.a) partial recombinant protein with GST tag. MW of the GST tag alone is 26 KDa.
<b>HOST SPECIES:</b>	Mouse

### Properties

<b>PURIFICATION:</b>	Protein A Column
<b>PHYSICAL STATE:</b>	Liquid
<b>BUFFER:</b>	PBS, pH 7.2
<b>STORAGE CONDITIONS:</b>	Store ART3 antibody at -20 °C. Aliquot to avoid freeze/thaw cycles.
<b>CLONALITY:</b>	Monoclonal
<b>ISOTYPE:</b>	IgG2b,k
<b>CONJUGATE:</b>	Unconjugated

### Additional Info

<b>ALTERNATE NAMES:</b>	ART3, ADP-ribosyltransferase 3, ARTC3, Ecto-ADP-ribosyltransferase 3, TMART, Mono(ADP-ribosyl)transferase 3, Mono-ADP-ribosyltransferase
<b>ACCESSION NO.:</b>	Q13508
<b>PROTEIN GI NO.:</b>	22261808
<b>OFFICIAL SYMBOL:</b>	ART3
<b>GENE ID:</b>	419

### Background

