




## Decorin Antibody [3H4-1F4]

CATALOG NUMBER: 51-449

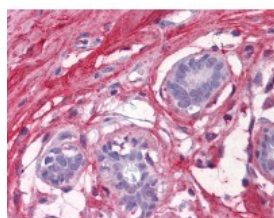

Immunohistochemistry of human breast tissue stained using Decorin Monoclonal Antibody.

### Specifications

<b>SPECIES REACTIVITY:</b>	Human
<b>TESTED APPLICATIONS:</b>	ELISA, IHC, WB
<b>APPLICATIONS:</b>	Decorin antibody can be used in Western Blot, and immunohistochemistry starting at 10 ug/mL.
<b>USER NOTE:</b>	Optimal dilutions for each application to be determined by the researcher.
<b>IMMUNOGEN:</b>	DCN (AAH05322, 1 a.a. ~ 360 a.a) full length recombinant protein with GST tag. MW of the GST tag alone is 26 KDa.
<b>HOST SPECIES:</b>	Mouse

### Properties

<b>PURIFICATION:</b>	Protein A Column
<b>PHYSICAL STATE:</b>	Liquid
<b>BUFFER:</b>	PBS, pH 7.2
<b>STORAGE CONDITIONS:</b>	Store Decorin antibody at -20 °C. Aliquot to avoid freeze/thaw cycles.
<b>CLONALITY:</b>	Monoclonal
<b>ISOTYPE:</b>	IgG2b,k
<b>CONJUGATE:</b>	Unconjugated

### Additional Info

<b>ALTERNATE NAMES:</b>	DCN, CSCD, Decorin proteoglycan, PG-S2, PG40, Proteoglycan core protein, SLRR1B, Small leucine-rich protein 1B, PGII, PGS2, Bone proteoglycan II, Decorin, DSPG2
<b>ACCESSION NO.:</b>	P07585
<b>PROTEIN GI NO.:</b>	129951
<b>OFFICIAL SYMBOL:</b>	DCN
<b>GENE ID:</b>	1634

### Background

