




## RPS7 Antibody [3G4]

CATALOG NUMBER: 51-504

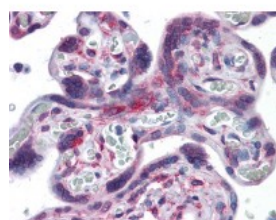

Immunohistochemistry of human placenta tissue stained using RPS7 Monoclonal Antibody.

### Specifications

<b>SPECIES REACTIVITY:</b>	Human, Mouse, Rat
<b>TESTED APPLICATIONS:</b>	ELISA, IF, IHC, WB
<b>APPLICATIONS:</b>	RPS7 antibody can be used in Western Blot starting at 1:500 - 1:1000, and immunohistochemistry starting at 10 ug/mL.
<b>USER NOTE:</b>	Optimal dilutions for each application to be determined by the researcher.
<b>IMMUNOGEN:</b>	RPS7 (NP_001002, 95 a.a. ~ 195 a.a) partial recombinant protein with GST tag. MW of the GST tag alone is 26 KDa.
<b>HOST SPECIES:</b>	Mouse

### Properties

<b>PURIFICATION:</b>	Protein A Column
<b>PHYSICAL STATE:</b>	Liquid
<b>BUFFER:</b>	PBS, pH 7.2
<b>STORAGE CONDITIONS:</b>	Store RPS7 antibody at -20 °C. Aliquot to avoid freeze/thaw cycles.
<b>CLONALITY:</b>	Monoclonal
<b>ISOTYPE:</b>	IgG1,k
<b>CONJUGATE:</b>	Unconjugated

### Additional Info

<b>ALTERNATE NAMES:</b>	RPS7, 40S ribosomal protein S7, Ribosomal protein S7, DBA8
<b>ACCESSION NO.:</b>	P62081
<b>PROTEIN GI NO.:</b>	49065831
<b>OFFICIAL SYMBOL:</b>	RPS7
<b>GENE ID:</b>	6201

### Background

