




CGGBP1 Antibody [1D11]

CATALOG NUMBER: 51-530

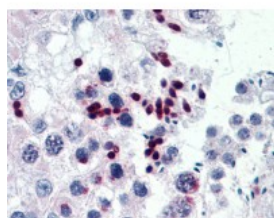

Immunohistochemistry of human testis
tissue stained using CGGBP1 Monoclonal
Antibody.

Specifications

SPECIES REACTIVITY:	Human
TESTED APPLICATIONS:	ELISA, IF, IHC, WB
APPLICATIONS:	CGGBP1 antibody can be used in Western Blot, and immunohistochemistry starting at 1:1000.
USER NOTE:	Optimal dilutions for each application to be determined by the researcher.
IMMUNOGEN:	CGGBP1 (NP_003654, 58 a.a. ~ 168 a.a) partial recombinant protein with GST tag. MW of the GST tag alone is 26 KDa.
HOST SPECIES:	Mouse

Properties

PURIFICATION:	Protein A Column
PHYSICAL STATE:	Liquid
BUFFER:	PBS, pH 7.2
STORAGE CONDITIONS:	Store CGGBP1 antibody at -20 °C. Aliquot to avoid freeze/thaw cycles.
CLONALITY:	Monoclonal
ISOTYPE:	IgG1,k
CONJUGATE:	Unconjugated

Additional Info

ALTERNATE NAMES:	CGGBP1, 20 kDa CGG-binding protein, CGGBP, p20-CGGBP, p20-CGGBP DNA-binding protein, CGG-binding protein 1, p20-CGG binding protein
ACCESSION NO.:	Q9UFW8
PROTEIN GI NO.:	116243045
OFFICIAL SYMBOL:	CGGBP1
GENE ID:	8545

Background

