




KHSRP Antibody [4C10]

CATALOG NUMBER: 51-531

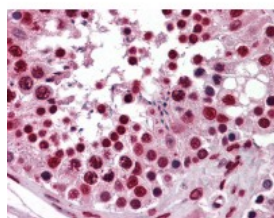

Immunohistochemistry of human testis tissue stained using KHSRP Monoclonal Antibody.

Specifications

SPECIES REACTIVITY:	Human
TESTED APPLICATIONS:	ELISA, IHC, WB
APPLICATIONS:	KHSRP antibody can be used in Western Blot, and immunohistochemistry starting at 20 ug/mL.
USER NOTE:	Optimal dilutions for each application to be determined by the researcher.
IMMUNOGEN:	KHSRP (NP_003676, 151 a.a. ~ 240 a.a) partial recombinant protein with GST tag. MW of the GST tag alone is 26 KDa.
HOST SPECIES:	Mouse

Properties

PURIFICATION:	Protein A Column
PHYSICAL STATE:	Liquid
BUFFER:	PBS, pH 7.2
STORAGE CONDITIONS:	Store KHSRP antibody at -20 °C. Aliquot to avoid freeze/thaw cycles.
CLONALITY:	Monoclonal
ISOTYPE:	IgG2b,k
CONJUGATE:	Unconjugated

Additional Info

ALTERNATE NAMES:	KHSRP, FUSE binding protein 2, KSRP, p75, FUBP2, FUSE-binding protein 2
ACCESSION NO.:	Q92945
PROTEIN GI NO.:	313104306
OFFICIAL SYMBOL:	KHSRP
GENE ID:	8570

Background

