




## BANF1 Antibody [3F10-4G12]

CATALOG NUMBER: 51-534

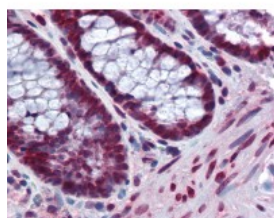

Immunohistochemistry of human colon tissue stained using BANF1 Monoclonal Antibody.

### Specifications

<b>SPECIES REACTIVITY:</b>	Human
<b>TESTED APPLICATIONS:</b>	ELISA, IHC, WB
<b>APPLICATIONS:</b>	BANF1 antibody can be used in Western Blot starting at 1: 500 - 1: 2000, and immunohistochemistry starting at 1:800.
<b>USER NOTE:</b>	Optimal dilutions for each application to be determined by the researcher.
<b>IMMUNOGEN:</b>	BANF1 (AAH05942, 1 a.a. ~ 90 a.a) full length recombinant protein with GST tag. MW of the GST tag alone is 26 KDa.
<b>HOST SPECIES:</b>	Mouse

### Properties

<b>PURIFICATION:</b>	Protein A Column
<b>PHYSICAL STATE:</b>	Liquid
<b>BUFFER:</b>	PBS, pH 7.2
<b>STORAGE CONDITIONS:</b>	Store BANF1 antibody at -20 °C. Aliquot to avoid freeze/thaw cycles.
<b>CLONALITY:</b>	Monoclonal
<b>ISOTYPE:</b>	IgG2a,k
<b>CONJUGATE:</b>	Unconjugated

### Additional Info

<b>ALTERNATE NAMES:</b>	BANF1, BCRG1, BCRP1, NGPS, BAF, D14S1460
<b>ACCESSION NO.:</b>	O75531
<b>PROTEIN GI NO.:</b>	5921173
<b>OFFICIAL SYMBOL:</b>	BANF1
<b>GENE ID:</b>	8815

### Background

