




COX17 Antibody [4G2]

CATALOG NUMBER: 51-548

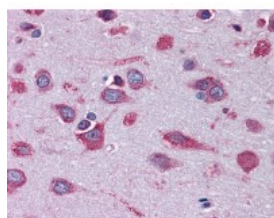

Immunohistochemistry of human brain
cortex tissue stained using COX17
Monoclonal Antibody.

Specifications

SPECIES REACTIVITY:	Human
TESTED APPLICATIONS:	ELISA, IHC, WB
APPLICATIONS:	COX17 antibody can be used in Western Blot, immunohistochemistry starting at 5 ug/mL, immunocytochemistry, and immunoprecipitation
USER NOTE:	Optimal dilutions for each application to be determined by the researcher.
IMMUNOGEN:	COX17 (NP_005685, 1 a.a. ~ 64 a.a) partial recombinant protein with GST tag. MW of the GST tag alone is 26 KDa.
HOST SPECIES:	Mouse

Properties

PURIFICATION:	Protein A Column
PHYSICAL STATE:	Liquid
BUFFER:	PBS, pH 7.2
STORAGE CONDITIONS:	Store COX17 antibody at -20 °C. Aliquot to avoid freeze/thaw cycles.
CLONALITY:	Monoclonal
ISOTYPE:	IgG2b,k
CONJUGATE:	Unconjugated

Additional Info

ALTERNATE NAMES:	COX17
ACCESSION NO.:	Q14061
PROTEIN GI NO.:	2493873
OFFICIAL SYMBOL:	COX17
GENE ID:	10063

Background

