




EPSTI1 Antibody [2A8]

CATALOG NUMBER: 51-599

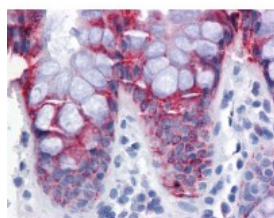

Immunohistochemistry of human colon tissue stained using EPSTI1 Monoclonal Antibody.

Specifications

SPECIES REACTIVITY:	Human
TESTED APPLICATIONS:	ELISA, IHC, WB
APPLICATIONS:	EPSTI1 antibody can be used in Western Blot, immunohistochemistry starting at 10 ug/mL, and immunoprecipitation.
USER NOTE:	Optimal dilutions for each application to be determined by the researcher.
IMMUNOGEN:	EPSTI1 (NP_001002264, 1 a.a. ~ 101 a.a) partial recombinant protein with GST tag. MW of the GST tag alone is 26 KDa.
HOST SPECIES:	Mouse

Properties

PURIFICATION:	Protein A Column
PHYSICAL STATE:	Liquid
BUFFER:	PBS, pH 7.2
STORAGE CONDITIONS:	Store EPSTI1 antibody at -20 °C. Aliquot to avoid freeze/thaw cycles.
CLONALITY:	Monoclonal
ISOTYPE:	IgG1,k
CONJUGATE:	Unconjugated

Additional Info

ALTERNATE NAMES:	EPSTI1, BRESI1
ACCESSION NO.:	Q96J88
PROTEIN GI NO.:	166232399
OFFICIAL SYMBOL:	EPSTI1
GENE ID:	94240

Background

