




GSTM2 Antibody [1E10]

CATALOG NUMBER: 51-954

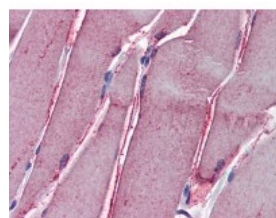

Immunohistochemistry of human skeletal muscle tissue stained using GSTM2 Monoclonal Antibody.

Specifications

SPECIES REACTIVITY:	Mouse
TESTED APPLICATIONS:	IHC, WB
APPLICATIONS:	GSTM2 antibody can be used in Western Blot starting at 1 - 2 ug/mL, and immunohistochemistry starting at 10 ug/mL.
USER NOTE:	Optimal dilutions for each application to be determined by the researcher.
IMMUNOGEN:	GSTM2 (NP_000839, 90 a.a. ~ 190 a.a) partial recombinant protein with GST tag. MW of the GST tag alone is 26 KDa.
HOST SPECIES:	Mouse

Properties

PURIFICATION:	Protein A Column
PHYSICAL STATE:	Liquid
BUFFER:	PBS, pH 7.2
STORAGE CONDITIONS:	Aliquot and store GSTM2 antibody at -20 °C or -80 °C. As with all antibodies avoid freeze/thaw cycles.
CLONALITY:	Monoclonal
ISOTYPE:	IgG1,k
CONJUGATE:	Unconjugated

Additional Info

ALTERNATE NAMES:	GSTM2, GSTM, Glutathione S-transferase Mu 2, GST class-mu 2, GST, muscle, GST4, GSTM2-2, Glutathione S-transferase 4, Glutathione S-transferase M1, GTHMUS
ACCESSION NO.:	P28161
PROTEIN GI NO.:	232204
OFFICIAL SYMBOL:	GSTM2
GENE ID:	2946

FOR RESEARCH USE ONLY

December 13, 2016