




HDAC1 Antibody [1D6]

CATALOG NUMBER: 51-957

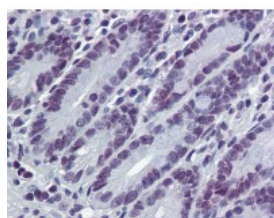

Immunohistochemistry of human small intestine tissue stained using HDAC1 Monoclonal Antibody.

Specifications

SPECIES REACTIVITY:	Human, Mouse, Rat
TESTED APPLICATIONS:	ELISA, IF, IHC, WB
APPLICATIONS:	HDAC1 antibody can be used in Western Blot starting at 1 - 2 ug/mL, and immunohistochemistry starting at 5 ug/mL.
USER NOTE:	Optimal dilutions for each application to be determined by the researcher.
IMMUNOGEN:	HDAC1 (AAH00301, 1 a.a. ~ 483 a.a) full length recombinant protein with GST tag. MW of the GST tag alone is 26 KDa.
HOST SPECIES:	Mouse

Properties

PURIFICATION:	Protein A Column
PHYSICAL STATE:	Liquid
BUFFER:	PBS, pH 7.2
STORAGE CONDITIONS:	Aliquot and store HDAC1 antibody at -20 °C or -80 °C. As with all antibodies avoid freeze/thaw cycles.
CLONALITY:	Monoclonal
ISOTYPE:	IgG1,k
CONJUGATE:	Unconjugated

Additional Info

ALTERNATE NAMES:	HDAC1, Histone deacetylase 1, GON-10, HD1, RPD3, RPD3L1
ACCESSION NO.:	Q13547
PROTEIN GI NO.:	2498443
OFFICIAL SYMBOL:	HDAC1
GENE ID:	3065

Background

