




FOXA1 Antibody [1B1]

CATALOG NUMBER: 51-962

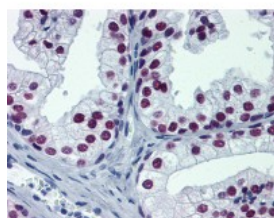

Immunohistochemistry of human prostate tissue stained using FOXA1 Monoclonal Antibody.

Specifications

SPECIES REACTIVITY:	Human
TESTED APPLICATIONS:	ELISA, IF, IHC, WB
APPLICATIONS:	FOXA1 antibody can be used in Western Blot starting at 1 - 2 ug/mL, and immunohistochemistry starting at 10 ug/mL.
USER NOTE:	Optimal dilutions for each application to be determined by the researcher.
IMMUNOGEN:	FOXA1 (NP_004487, 367 a.a. ~ 473 a.a) partial recombinant protein with GST tag. MW of the GST tag alone is 26 KDa.
HOST SPECIES:	Mouse

Properties

PURIFICATION:	Protein A Column
PHYSICAL STATE:	Liquid
BUFFER:	PBS, pH 7.2
STORAGE CONDITIONS:	Aliquot and store FOXA1 antibody at -20 °C or -80 °C. As with all antibodies avoid freeze/thaw cycles.
CLONALITY:	Monoclonal
ISOTYPE:	IgG2a,k
CONJUGATE:	Unconjugated

Additional Info

ALTERNATE NAMES:	FOXA1, Forkhead box A1, Forkhead box protein A1, HNF-3-alpha, HNF-3A, TCF-3A, TCF3A, HNF3A, Transcription factor 3A
ACCESSION NO.:	P55317
PROTEIN GI NO.:	296434509
OFFICIAL SYMBOL:	FOXA1
GENE ID:	3169

FOR RESEARCH USE ONLY

December 13, 2016