




ADAMTS1 Antibody

CATALOG NUMBER: 48-132

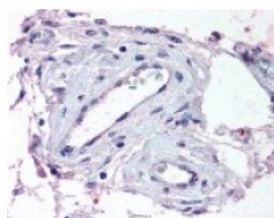

Immunohistochemistry staining of
ADAMTS1 in testis, vessels tissue using
ADAMTS1 Antibody.

Specifications

SPECIES REACTIVITY:	Gorilla, Human
TESTED APPLICATIONS:	IHC
APPLICATIONS:	ADAMTS1 antibody can be used in ELISA, Western Blot, and immunohistochemistry starting at 5 ug/mL.
USER NOTE:	Optimal dilutions for each application to be determined by the researcher.
SPECIFICITY:	BLAST analysis of the peptide immunogen showed no homology with other human proteins.
IMMUNOGEN:	ADAMTS1 antibody was raised against a peptide located near the internal domain of ADAMTS1 (Human).
HOST SPECIES:	Rabbit

Properties

PURIFICATION:	Immunoaffinity Chromatography
PHYSICAL STATE:	Liquid
BUFFER:	PBS, 0.1% sodium azide.
STORAGE CONDITIONS:	Store ADAMTS1 antibody at 4 °C for short term applications. For long term storage, aliquot and -20 °C.
CLONALITY:	Polyclonal
CONJUGATE:	Unconjugated

Additional Info

ALTERNATE NAMES:	ADAMTS1, ADAM-TS, ADAMTS-1, ADAM-TS 1, C3-C5, ADAM-TS1, METH-1, METH1, KIAA1346
ACCESSION NO.:	Q9UHI8
PROTEIN GI NO.:	124053460
OFFICIAL SYMBOL:	ADAMTS1
GENE ID:	9510

Background

BACKGROUND:	ADAMTS1 is a Metallopeptidase M12B type protease.
--------------------	---

