




USP4 Antibody

CATALOG NUMBER: 48-363

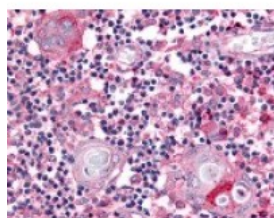

Immunohistochemistry staining of USP4 in thymus tissue using USP4 Antibody.

Specifications

SPECIES REACTIVITY:	Bat, Bovine, Dog, Gibbon, Gorilla, Horse, Human, Monkey, Orangutan, Pig, Rabbit
TESTED APPLICATIONS:	IHC
APPLICATIONS:	USP4 antibody can be used in ELISA, Western Blot starting at 1:500 - 1:1000, immunohistochemistry starting at 5 ug/mL, and immunoprecipitation
USER NOTE:	Optimal dilutions for each application to be determined by the researcher.
SPECIFICITY:	BLAST analysis of the peptide immunogen showed no homology with other human proteins, except USP15 (67%).
IMMUNOGEN:	USP4 antibody was raised against a peptide located near the internal domain of USP4 (Human).
HOST SPECIES:	Rabbit

Properties

PURIFICATION:	Immunoaffinity Chromatography
PHYSICAL STATE:	Liquid
BUFFER:	PBS, 0.1% sodium azide.
STORAGE CONDITIONS:	USP4 antibody should be stored long term (months) at -80 °C and short term (days) at 4 °C. As with all antibodies avoid freeze/thaw cycles.
CLONALITY:	Polyclonal
CONJUGATE:	Unconjugated

Additional Info

ALTERNATE NAMES:	USP4, Deubiquitinating enzyme 4, Unph, Ubiquitin thiolesterase 4, Ubiquitin thioesterase 4, Ubiquitin-specific protease 4, UNP
ACCESSION NO.:	Q13107
PROTEIN GI NO.:	116242839
OFFICIAL SYMBOL:	USP4
GENE ID:	7375

FOR RESEARCH USE ONLY

December 13, 2016