




NCK2 Antibody

CATALOG NUMBER: 48-611

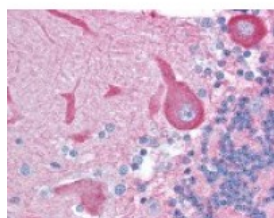

Immunohistochemistry staining of NCK2 in cerebellum tissue using NCK2 Antibody.

Specifications

SPECIES REACTIVITY:	Human
TESTED APPLICATIONS:	IHC
APPLICATIONS:	NCK2 antibody can be used in Western Blot, immunohistochemistry starting at 10 ug/mL, and flow cytometry starting at 1:50 - 1:100.
USER NOTE:	Optimal dilutions for each application to be determined by the researcher.
IMMUNOGEN:	NCK2 antibody was raised against amino acids 119 - 276 of NCK2 (Human).
HOST SPECIES:	Rabbit

Properties

PHYSICAL STATE:	Liquid
BUFFER:	PBS, pH 7.4, 0.2% BSA, 0.05% sodium azide.
STORAGE CONDITIONS:	Store NCK2 antibody at 4 °C, Avoid Freezing
CLONALITY:	Polyclonal
CONJUGATE:	Unconjugated

Additional Info

ALTERNATE NAMES:	NCK2, GRB4, NCKbeta, NCK beta, Nck-2, Cytoplasmic protein NCK2, NCK adaptor protein 2
ACCESSION NO.:	O43639
PROTEIN GI NO.:	20532395
OFFICIAL SYMBOL:	NCK2
GENE ID:	8440

Background

FOR RESEARCH USE ONLY