




FGFR4 Antibody [4H2B10B2]

CATALOG NUMBER: 49-057

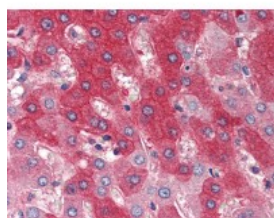

Human liver tissue stained with FGFR4
Antibody, alkaline phosphatase-
streptavidin and chromogen.

Specifications

SPECIES REACTIVITY:	Human
TESTED APPLICATIONS:	ELISA, IHC, WB
APPLICATIONS:	FGFR4 antibody can be used in ELISA, Western Blot, and immunohistochemistry starting at 2.5 ug/mL.
USER NOTE:	Optimal dilutions for each application to be determined by the researcher.
IMMUNOGEN:	Ni-NTA purified truncated recombinant FGFR4-Trx-His expressed in E. Coli strain BL21 (DE3)
HOST SPECIES:	Mouse

Properties

PURIFICATION:	Ascites
PHYSICAL STATE:	Liquid
BUFFER:	0.03% sodium azide.
STORAGE CONDITIONS:	Store FGFR4 antibody at 4 °C or -20 °C. As with all antibodies avoid freeze/thaw cycles.
CLONALITY:	Monoclonal
ISOTYPE:	IgG 1
CONJUGATE:	Unconjugated

Additional Info

ALTERNATE NAMES:	FGFR4, CD334, CD334 antigen, Hydroxyaryl-protein kinase, FGFR-4, JTK2, TKF, Tyrosylprotein kinase, FGF receptor 4, Protein-tyrosine kinase
ACCESSION NO.:	P22455
PROTEIN GI NO.:	13432140
OFFICIAL SYMBOL:	FGFR4
GENE ID:	2264

Background

