




SIRT6 Antibody

CATALOG NUMBER: 49-730

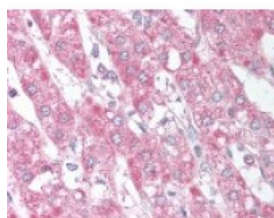

Immunohistochemistry staining of SIRT6 in adrenal (formalin-fixed paraffin embedded) tissue using SIRT6 Antibody.

Specifications

SPECIES REACTIVITY:	Human
TESTED APPLICATIONS:	ELISA, IHC
APPLICATIONS:	SIRT6 antibody can be used in ELISA starting at 1:5000 - 1:25000, Western Blot starting at 1:200 - 1:2000, immunohistochemistry starting at 20 ug/mL, and immunofluorescence.
USER NOTE:	Optimal dilutions for each application to be determined by the researcher.
IMMUNOGEN:	Amino acids 305 to 320 of human SIRT6
HOST SPECIES:	Rabbit

Properties

PURIFICATION:	Protein G Column
PHYSICAL STATE:	Liquid
BUFFER:	PBS, 0.1% sodium azide.
STORAGE CONDITIONS:	SIRT6 antibody should be stored long term (months) at -20 °C and short term (weeks) at 4 °C. As with all antibodies avoid freeze/thaw cycles.
CLONALITY:	Polyclonal
CONJUGATE:	Unconjugated

Additional Info

ALTERNATE NAMES:	SIRT6, SIR2-like protein 6, Sirtuin type 6, SIR2L6, Sir2-related protein type 6, Sirtuin 6
ACCESSION NO.:	Q8N6T7
PROTEIN GI NO.:	38258612
OFFICIAL SYMBOL:	SIRT6
GENE ID:	51548

Background

FOR RESEARCH USE ONLY

