




PCBP2 Antibody [5F12]

CATALOG NUMBER: 51-496

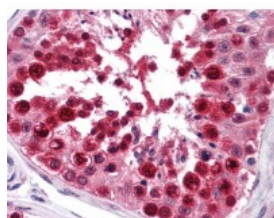

Immunohistochemistry of human testis tissue stained using PCBP2 Monoclonal Antibody.

Specifications

SPECIES REACTIVITY:	Human
TESTED APPLICATIONS:	ELISA, IF, IHC, RNAi, WB
APPLICATIONS:	PCBP2 antibody can be used in Western Blot, and immunohistochemistry starting at 5 ug/mL.
USER NOTE:	Optimal dilutions for each application to be determined by the researcher.
IMMUNOGEN:	PCBP2 (AAH01155, 1 a.a. ~ 363 a.a) full length recombinant protein with GST tag. MW of the GST tag alone is 26 KDa.
HOST SPECIES:	Mouse

Properties

PURIFICATION:	Protein A Column
PHYSICAL STATE:	Liquid
BUFFER:	PBS, pH 7.2
STORAGE CONDITIONS:	Store PCBP2 antibody at -20 °C. Aliquot to avoid freeze/thaw cycles.
CLONALITY:	Monoclonal
ISOTYPE:	IgG2a,k
CONJUGATE:	Unconjugated

Additional Info

ALTERNATE NAMES:	PCBP2, Alpha-CP2, HnRNP E2, HNRPE2, Poly(rC) binding protein 2, Poly(rC)-binding protein 2, HnRNP-E2
ACCESSION NO.:	Q15366
PROTEIN GI NO.:	6707736
OFFICIAL SYMBOL:	PCBP2
GENE ID:	5094

Background

