




SELPLG Antibody [HECA-452]

CATALOG NUMBER: 51-833

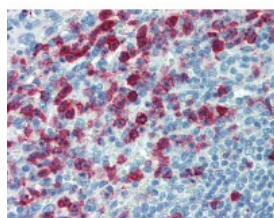

Immunohistochemistry of human spleen tissue stained using SELPLG Monoclonal Antibody.

Specifications

SPECIES REACTIVITY:	Human, Mouse
TESTED APPLICATIONS:	FACS, IHC
APPLICATIONS:	SELPLG antibody can be used in immunohistochemistry starting at 10 ug/mL.
USER NOTE:	Optimal dilutions for each application to be determined by the researcher.
IMMUNOGEN:	Stromal preparation from human tonsils
HOST SPECIES:	Rat

Properties

PURIFICATION:	Affinity Chromatography
PHYSICAL STATE:	Liquid
BUFFER:	Phosphate-buffered solution, pH 7.2, 0.09% sodium azide.
STORAGE CONDITIONS:	Store SELPLG antibody at 4 °C, Avoid Freezing
CLONALITY:	Monoclonal
ISOTYPE:	IgM
CONJUGATE:	Unconjugated

Additional Info

ALTERNATE NAMES:	SELPLG, CD162 antigen, CLA, CD162, PSGL1, PSGL-1, Selectin P ligand
ACCESSION NO.:	Q14242
PROTEIN GI NO.:	2498904
OFFICIAL SYMBOL:	SELPLG
GENE ID:	6404

Background

FOR RESEARCH USE ONLY

