




## SOX10 Antibody [1E6]

CATALOG NUMBER: 70-035

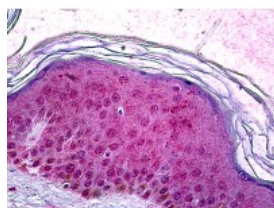

Immunohistochemistry of human skin tissue stained using SOX10 Monoclonal Antibody.

### Specifications

<b>SPECIES REACTIVITY:</b>	Human
<b>TESTED APPLICATIONS:</b>	ELISA, IHC, WB
<b>APPLICATIONS:</b>	SOX10 antibody can be used in Western Blot starting at 1 - 3 ug/mL, immunohistochemistry starting at 5 ug/mL, and flow cytometry.
<b>USER NOTE:</b>	Optimal dilutions for each application to be determined by the researcher.
<b>IMMUNOGEN:</b>	Recombinant protein
<b>HOST SPECIES:</b>	Mouse

### Properties

<b>PURIFICATION:</b>	Protein A Column
<b>PHYSICAL STATE:</b>	Liquid
<b>BUFFER:</b>	PBS, pH 7.2
<b>STORAGE CONDITIONS:</b>	SOX10 antibody can be stored short term 4 °C. For long term storage aliquot and store at -20 °C. As with all antibodies avoid freeze/thaw cycles.
<b>CLONALITY:</b>	Monoclonal
<b>ISOTYPE:</b>	IgG2a,k
<b>CONJUGATE:</b>	Unconjugated

### Additional Info

<b>ALTERNATE NAMES:</b>	SOX10, DOM, Transcription factor SOX-10, WS4, PCWH, WS2E, SRY-related HMG-box gene 10, WS4C
<b>ACCESSION NO.:</b>	P56693
<b>PROTEIN GI NO.:</b>	6175075
<b>OFFICIAL SYMBOL:</b>	SOX10
<b>GENE ID:</b>	6663

### Background

