


GAS41 (YEATS4/NuBI-1) Antibody (N-term A31)

Purified Rabbit Polyclonal Antibody (Pab)

Catalog #	Applications:	Reactivity:	Accessions:
AP1910a	WB, E	H	O95619
Concentration:	Size:	Isotype:	Clone Name:
0.25 mg/ml	0.1 mg	Rabbit Ig	RB8349

Application Data: **Calculated MW: 26499 Da**

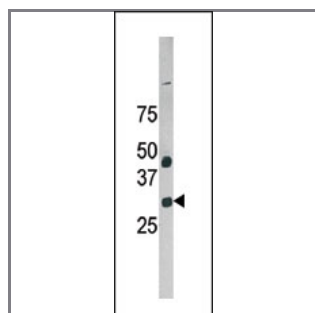

Western blot analysis of anti-NuBI-1 Pab (Cat. #AP1910a) in HepG2 cell line lysate. NuBI-1 (arrow) was detected using the purified Pab.

Gene ID: [8089](#) **Gene Symbol:** YEATS4

Other Names:

YEATS domain-containing protein 4; Glioma-amplified sequence-41; Gas41; NuMA binding protein 1; NuBI-1; NuBI1; YEATS4; GAS41;

Target/Specificity:

This GAS41 (YEATS4/NuBI-1) antibody is generated from rabbits immunized with a KLH conjugated synthetic peptide between 24~53 amino acids from the N-terminal region of human NuBI-1.

Application Notes:

The suggested dilution is:

ELISA 1:1,000

Western blotting 1:100~500

Format:

Purified polyclonal antibody supplied in PBS with 0.09% (W/V) sodium azide. This antibody is prepared by Saturated Ammonium Sulfate (SAS) precipitation followed by dialysis against PBS.

Storage:

Maintain refrigerated at 2-8°C for up to 6 months. For long term storage store at -20°C in small aliquots to prevent freeze-thaw cycles.

Precautions:

GAS41 (YEATS4/NuBI-1) Antibody (N-term A31) is for research use only and not for use in diagnostic or therapeutic procedures.
