


Mouse Stk10 Antibody (C-term)

Peptide Affinity Purified Rabbit Polyclonal Antibody (Pab)

Catalog #	Applications:	Reactivity:	Accessions:
AP14636b	WB, E	M	O55098
Concentration:	Size:	Isotype:	Clone Name:
0.25 mg/ml	0.1 mg	Rabbit Ig	RB35148

Application Data:

Calculated MW: 111993 Da

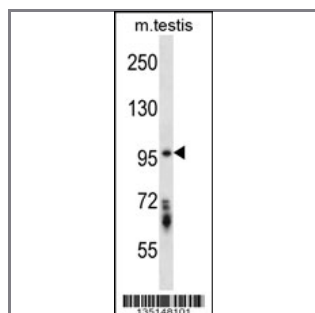

Mouse Stk10 Antibody (C-term) (Cat. #AP14636b) western blot analysis in mouse testis tissue lysates (35ug/lane). This demonstrates the Stk10 antibody detected the Stk10 protein (arrow).

Gene ID:

Gene Symbol:

Stk10

Other Names:

Serine/threonine-protein kinase 10;Stk10;Lok

Target/Specificity:

This Mouse Stk10 antibody is generated from rabbits immunized with a KLH conjugated synthetic peptide between 667-696 amino acids from the C-terminal region of Mouse Stk10.

Application Notes:

The suggested dilution is:

ELISA 1:1,000

Western blotting 1:100~500

Format:

Purified polyclonal antibody supplied in PBS with 0.09% (W/V) sodium azide. This antibody is purified through a protein A column, followed by peptide affinity purification.

Storage:

Mouse Stk10 Antibody (C-term) can be refrigerated at 2-8°C for up to 6 months. For long term

storage, place the at -20°C.

Precautions:

Mouse Stk10 Antibody (C-term) is for research use only and not for use in diagnostic or therapeutic procedures.
