


ANKS4B Antibody (Center)

Peptide Affinity Purified Rabbit Polyclonal Antibody (Pab)

Catalog #	Applications:	Reactivity:	Accessions:
AP14720c	WB, E	H	NP_665872.2 , Q8N8V4
Concentration:	Size:	Isotype:	Clone Name:
0.25 mg/ml	0.1 mg	Rabbit Ig	RB34888

Application Data:

Calculated MW: 51187 Da

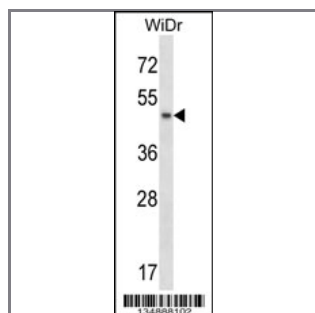

ANKS4B Antibody (Center) (Cat. #AP14720c) western blot analysis in WiDr cell line lysates (35ug/lane). This demonstrates the ANKS4B antibody detected the ANKS4B protein (arrow).

Gene ID:	Gene Symbol:
257629	ANKS4B

Other Names:

Ankyrin repeat and SAM domain-containing protein 4B;ANKS4B;HARP

Target/Specificity:

This ANKS4B antibody is generated from rabbits immunized with a KLH conjugated synthetic peptide between 183-213 amino acids from the Central region of human ANKS4B.

Application Notes:

The suggested dilution is:

ELISA 1:1,000

Western blotting 1:100~500

Format:

Purified polyclonal antibody supplied in PBS with 0.09% (W/V) sodium azide. This antibody is purified through a protein A column, followed by peptide affinity purification.

Storage:

ANKS4B Antibody (Center) can be refrigerated at 2-8°C for up to 6 months. For long term storage,

place the at -20°C.

Precautions:

ANKS4B Antibody (Center) is for research use only and not for use in diagnostic or therapeutic procedures.
