


TLE4 Antibody (Center)(Ascites)

Mouse Monoclonal Antibody (Mab)

Catalog #	Applications:	Reactivity:	Accessions:
AM2017a	WB, E	H	NP_008936.2 , Q04727

Concentration:	Size:	Isotype:	Clone Name:
Crude ascites	0.1 ml	IgM	384CT24.1.3.4

Application Data: **Calculated MW: 83755 Da**

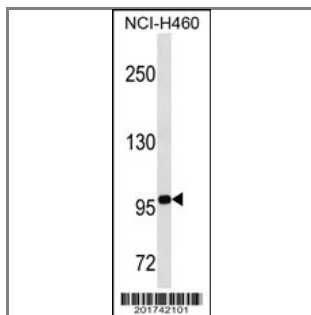

TLE4 Antibody (Center) (Cat. #AM2017a) western blot analysis in NCI-H460 cell line lysates (35ug/lane). This demonstrates the TLE4 antibody detected the TLE4 protein (arrow).

Gene ID:	Gene Symbol:
7091	TLE4

Other Names:

Transducin-like enhancer protein 4;TLE4;KIAA1261

Target/Specificity:

This TLE4 Monoclonal antibody is generated from mice immunized with a KLH conjugated synthetic peptide selected from the center region of human TLE4.

Application Notes:

The suggested dilution is:

ELISA 1:1,000

Western blotting 1:100~3200

Format:

Mouse monoclonal antibody supplied in crude ascites with 0.09% (W/V) sodium azide.

Storage:

TLE4 Antibody (Center)(Ascites) can be refrigerated at 2-8°C for up to 6 months. For long term storage, place the at -20°C.

Precautions:

TLE4 Antibody (Center)(Ascites) is for research use only and not for use in diagnostic or therapeutic procedures.
