

AHCY Antibody(Ascites)


Mouse Monoclonal Antibody (Mab)

Catalog #	Applications:	Reactivity:	Accessions:
AM2030a	WB, E	H, M	NP_000678.1 , NP_001155238.1 , P23526

Concentration:	Size:	Isotype:	Clone Name:
Crude ascites	0.1 ml	IgM	445CT13.3.3

Application Data:

Calculated MW: 47716 Da

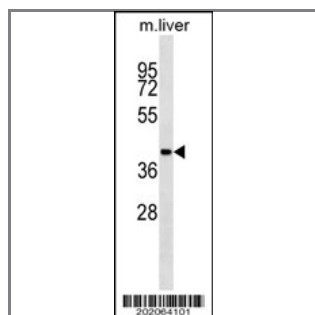

AHCY Antibody (Cat. #AM2030a) western blot analysis in mouse liver tissue lysates (35ug/lane). This demonstrates the AHCY antibody detected the AHCY protein (arrow).

Gene ID:	Gene Symbol:
191	AHCY

Other Names:

Adenosylhomocysteinase;AHCY;SAHH

Target/Specificity:

Purified His-tagged AHCY protein(Fragment) was used to produced this monoclonal antibody.

Application Notes:

The suggested dilution is:

ELISA 1:1,000

Western blotting 1:1000~8000

Format:

Mouse monoclonal antibody supplied in crude ascites with 0.09% (W/V) sodium azide.

Storage:

AHCY Antibody(Ascites) can be refrigerated at 2-8°C for up to 6 months. For long term storage,

place the at -20°C.

Precautions:

AHCY Antibody(Ascites) is for research use only and not for use in diagnostic or therapeutic procedures.
